

Part No: 3929-180C

**Fabricated CPVC Schedule 80 Couplings
DWV**

Desc: 18 CPVC COUPLING SOC SCH80

MSRP: 6583.16

Part Code: 099

Weight(lbs): 72.951

Weight(kg): 33.09

Weight(gm): 33090


Size: 18

Color: GRAY

Material: CPVC

Type Standard

Connection Socket X Socket

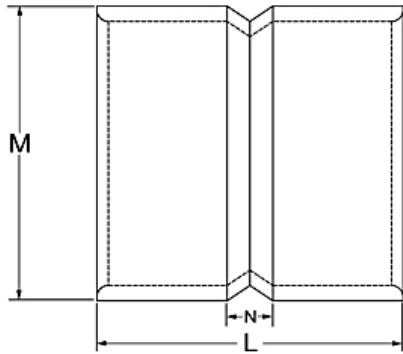

L = 22

M = 19-7/8

N = 4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

