

Part No: 3929-338CE

**Fabricated CPVC Schedule 80 Couplings
DWV**

Desc: 3X2 CPVC ECC RD CPLNG SOC SCH80

MSRP: 109.43

Part Code: 099

Weight(lbs): 1.071


Weight(kg): 0.486

Weight(gm): 486

Size: 3 X 2

Color: GRAY

Material: CPVC

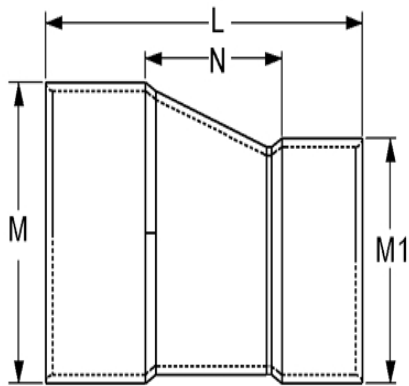

Type Eccentric Reduction

Connection Socket X Socket

M = 3-15/16

M1 = 2-13/16

L = 8-1/8

N = 4-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

