

Part No: 3929-624

Fabricated DWV

Couplings

Desc: 10X4 PVC RED COUP SOC SCH80

MSRP: 643.02

Part Code: 400

Weight(lbs): 14.771


Weight(kg): 6.7

Weight(gm): 6700

Size: 10 X 4

Color: GRAY

Material: PVC

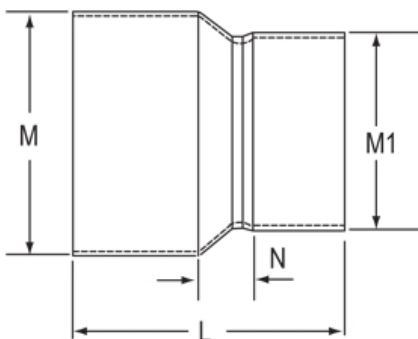

L = 21-1/8

M = 11-3/4

M1 = 5-3/16

N = 13-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

