

Part No: 3929-626E

Fabricated DWV

Couplings

Desc: 10X6 PVC RED COUP ECC SOC SCH80

MSRP: 457

Part Code: 400

Weight(lbs): 18.629

Weight(kg): 8.45

Weight(gm): 8450


Size: 10 X 6

Color: GRAY

Material: PVC

Schedule SCH 80 DWV- Eccentric Reducer

Connection Socket x Socket

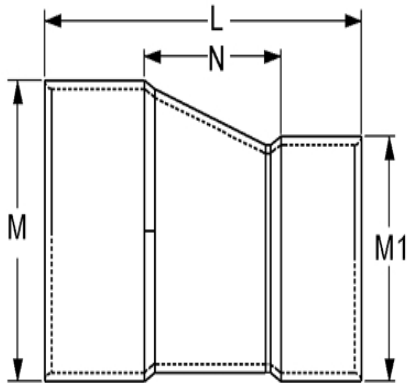

L = 26- 3/8

M = 11- 3/4

M1 = 7- 1/2

N = 17- 7/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

