

Part No: 3929-668C

**Fabricated CPVC Schedule 80 Couplings
DWV**

Desc: 12X8 CPVC RED COUPLING SOC SCH80

MSRP: 1715.97

Part Code: 099

Weight(lbs): 27.029

Weight(kg): 12.26

Weight(gm): 12260


Size: 12 X 8

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket X Socket

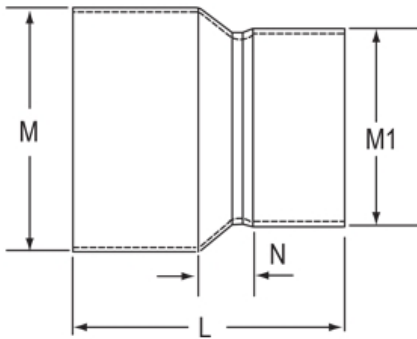

N = 10-1/8

L = 20-5/8

M = 13-15/16

M1 = 9-5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

