

**Part No:** 3929-758E

**Fabricated DWV**

**Couplings**

**Desc:** 16X8 PVC ECC RED COUP SOC SCH80

**MSRP:** 2269.27

**Part Code:** 400

**Weight(lbs):** 69.798

**Weight(kg):** 31.66

**Weight(gm):** 31660


**Size:** 16 X 8

**Color:** GRAY

**Material:** PVC

**Schedule** SCH 80 DWV- Eccentric Reducer

**Connection** Socket x Socket

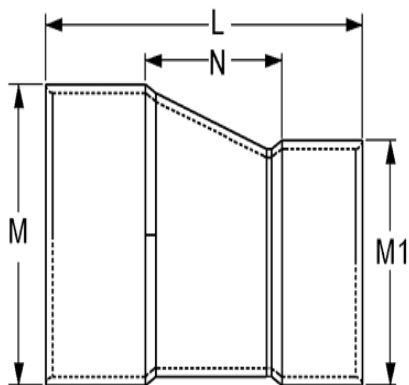

**M** = 17-1/2

**M1** = 9-5/8

**L** = 45-15/16

**N** = 33-11/16

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

