

Part No: 3929-760C

Fabricated CPVC Schedule 80 Couplings
DWV

Desc: 16X10 CPVC RED COUPLING SOC SCH80

MSRP: 4197.32

Part Code: 099

Weight(lbs): 45.651

Weight(kg): 20.707

Weight(gm): 20707


Size: 16 X 10

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket X Socket

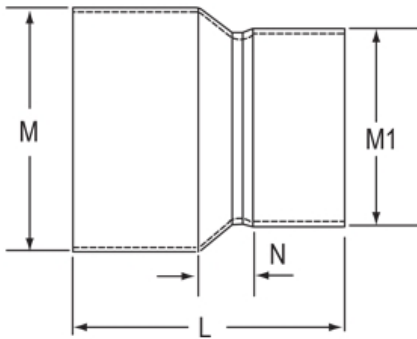

L = 26

M = 17-3/8

M1 = 11-15/16

N = 12-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

