

Part No: 3929-762E

Fabricated DWV

Couplings

Desc: 16X12 PVC ECC RED COUP SOC SCH80

MSRP: 1465.66

Part Code: 400

Weight(lbs): 64.155

Weight(kg): 29.1

Weight(gm): 29100


Size: 16 X 12

Color: GRAY

Material: PVC

Schedule SCH 80 DWV- Eccentric Reducer

Connection Socket x Socket

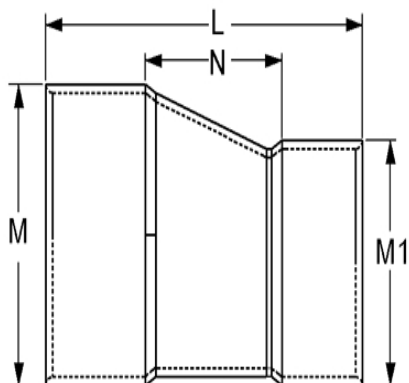

M = 17-1/2

M1 = 14-1/8

L = 33

N = 18-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

