

Part No: 3929-788E

Fabricated DWV

Couplings

Desc: 18X8 PVC RED COUP ECC SOC SCH80

MSRP: 3274.66

Part Code: 400

Weight(lbs): 122.026

Weight(kg): 55.35

Weight(gm): 55350


Size: 18 X 8

Color: GRAY

Material: PVC

Schedule SCH 80 DWV- Eccentric Reducer

Connection Socket x Socket

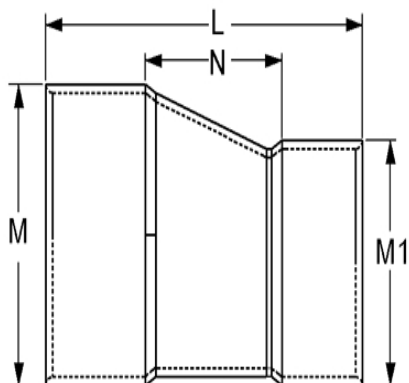

M = 19-11/16

M1 = 9-5/8

L = 60-15/16

N = 47-11/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

