

Part No: 3929-790C

Fabricated CPVC Schedule 80 Couplings
DWV

Desc: 18X10 CPVC RED COUPLING SOC SCH80

MSRP: 5827.41

Part Code: 099

Weight(lbs): 89.618

Weight(kg): 40.65

Weight(gm): 40650


Size: 18 X 10

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket X Socket

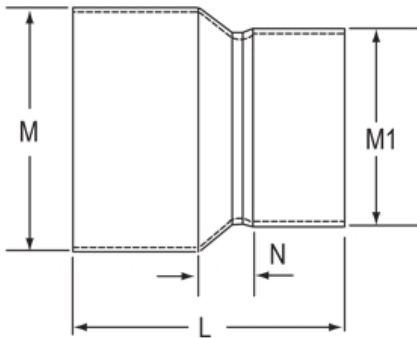

L = 35-3/8

M = 19-11/16

M1 = 11-15/16

N = 21-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

