

Part No: 3929-792E

Fabricated DWV

Couplings

Desc: 18X12 PVC RED COUP ECC SOC SCH80

MSRP: 2731.36

Part Code: 400

Weight(lbs): 109.9

Weight(kg): 49.85

Weight(gm): 49850


Size: 18 X 12

Color: GRAY

Material: PVC

Schedule SCH 80 DWV- Eccentric Reducer

Connection Socket x Socket

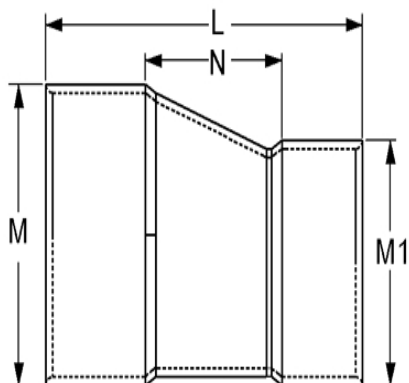

M = 19-11/16

M1 = 14-1/8

L = 48

N = 32-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

