

Part No: 3942-060

Fabricated DWV

Elbows

Desc: 6 PVC 22-1/2 ST ELL SPGXSOC SCH80

MSRP: 183.46

Part Code: 400

Weight(lbs): 5.146

Weight(kg): 2.334

Weight(gm): 2334

Size: 6


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Spigot x Socket

Angle 22-1/2° Street

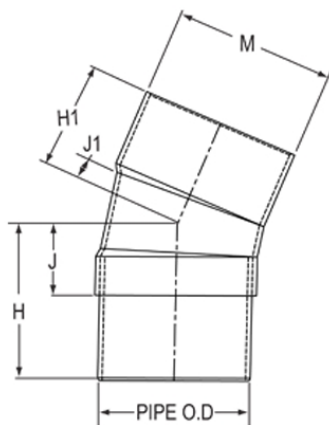

M1 = 7-1/2

H = 6-5/8

H1 = 3-5/16

J = 2-5/8

J1 = 1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

