

Part No: 3942-080

Fabricated DWV

Elbows

Desc: 8 PVC 22-1/2 ST ELL SPGXSOC SCH80

MSRP: 300.36

Part Code: 400

Weight(lbs): 9.949

Weight(kg): 4.513

Weight(gm): 4513

Size: 8


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Spigot x Socket

Angle 22-1/2° Street

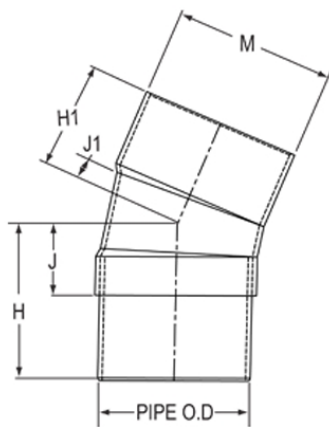

H = 8-11/16

H1 = 3-9/16

J = 3-11/16

J1 = 11/16

M1 = 9-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

