

Part No: 3942-140C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 14 CPVC 22-1/2 ST ELL SPIGOTXSOC SCH80

MSRP: 3169.48

Part Code: 099

Weight(lbs): 41.557

Weight(kg): 18.85

Weight(gm): 18850


Size: 14

Color: GRAY

Material: CPVC

Connection Spigot X Socket

Angle 22-1/2° Street

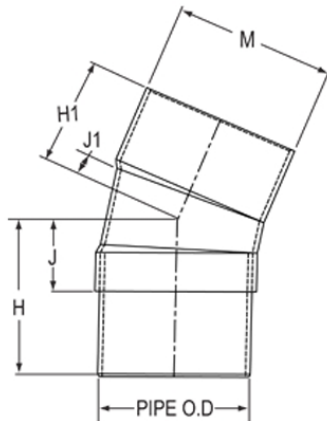

H = 14-1/16

H1 = 6-5/16

J = 6-1/16

J1 = 11/16

M = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

