

Part No: 3942-180C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 18 CPVC 22-1/2 ST ELL SPIGOTXSOC SCH80

MSRP: 7031.88

Part Code: 099

Weight(lbs): 74.507

Weight(kg): 33.796

Weight(gm): 33796


Size: 18

Color: GRAY

Material: CPVC

Connection Spigot X Socket

Angle 22-1/2° Street

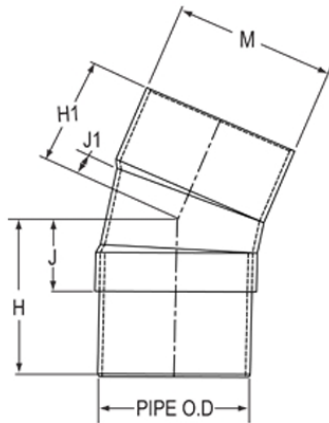

H = 18-1/4

H1 = 12-3/4

J = 8-1/4

J1 = 3-3/4

M = 19-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

