

Part No: 3963-826

Fabricated DWV

Glue-on Saddles

Desc: 20X16 PVC SADDLE SOC SCH80 N.P.R.

MSRP: 994.07

Part Code: 400

Weight(lbs): 24.205

Weight(kg): 10.979

Weight(gm): 10979


Size: 20 X 16

Color: GRAY

Material: PVC

Schedule SCH 80 DWV Saddle

Connection Socket

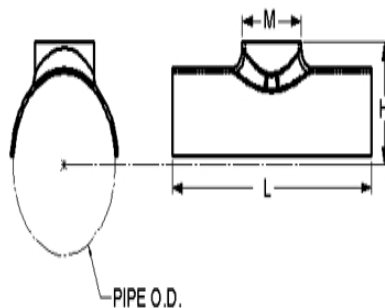

H = 12-11/16

L = 26

M = 17-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

