

Part No: 3963-918C

**Fabricated CPVC Schedule 80 Glue on Saddles
DWV**

Desc: 24X18 CPVC SADDLE SOC SCH80 N.P.R.

MSRP: 3348.51

Part Code: 099

Weight(lbs): 30.898

Weight(kg): 14.015

Weight(gm): 14015


Size: 24 X 18

Color: GRAY

Material: CPVC

Type Saddle

Connection IPS O.D. X Socket

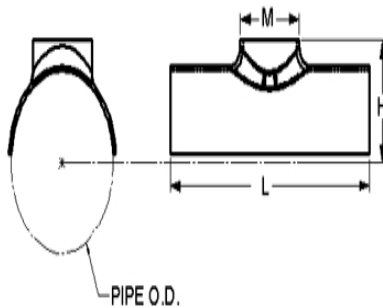

H = 14-11/16

L = 28

M = 19-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

