

Part No: 3965-578

Fabricated DWV

Glue-on Saddles

Desc: 8X2 PVC STUB SADDLE SOC SCH80 N.P.R.

MSRP: 144.42

Part Code: 409

Weight(lbs): 2.116

Weight(kg): 0.96

Weight(gm): 960


Size: 8 X 2

Color: GRAY

Material: PVC

Schedule SCH 80 DWV Stub Saddle

Connection Socket

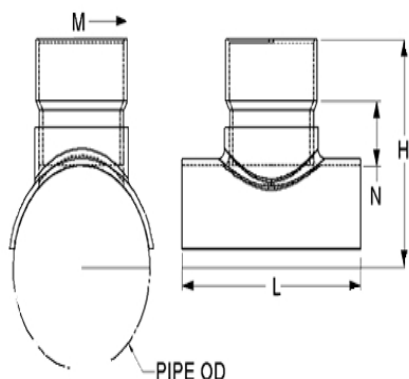

M = 2-13/16

N = 2-5/16

H = 8-3/8

L = 8-3/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

