

Part No: 3965-661C

**Fabricated CPVC Schedule 80 Glue on Saddles
DWV**

Desc: 12X2 CPVC STUB SADDLE SOC SCH80 N.P.R.

MSRP: 330.32

Part Code: 099

Weight(lbs): 2.535

Weight(kg): 1.15

Weight(gm): 1150


Size: 12 X 2

Color: GRAY

Material: CPVC

Type Stub Saddle

Connection IPS O.D. X Socket

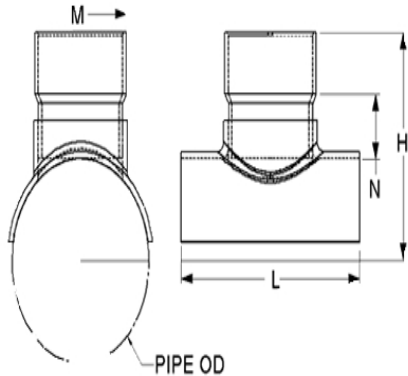

H = 10-7/16

L = 8-3/4

M = 2-13/16

N = 2-5/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

