

Part No: 3965-786C

**Fabricated CPVC Schedule 80 Glue on Saddles
DWV**

Desc: 18X6 CPVC STUB SADDLE SOC SCH80 N.P.R.

MSRP: 1050.23

Part Code: 099

Weight(lbs): 14.021

Weight(kg): 6.36

Weight(gm): 6360


Size: 18 X 6

Color: GRAY

Material: CPVC

Type Stub Saddle

Connection IPS O.D. X Socket

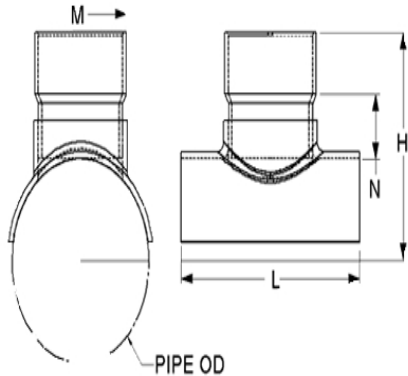

H = 16-1/2

L = 14-3/4

M = 7-1/2

N = 4-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

