

Part No: 3965-811C

**Fabricated CPVC Schedule 80 Glue on Saddles
DWV**

Desc: 20X2 CPVC STUB SADDLE SOC SCH80 N.P.R.

MSRP: 493.76

Part Code: 099

Weight(lbs): 3.144

Weight(kg): 1.426

Weight(gm): 1426


Size: 20 X 2

Color: GRAY

Material: CPVC

Type Stub Saddle

Connection IPS O.D. X Socket

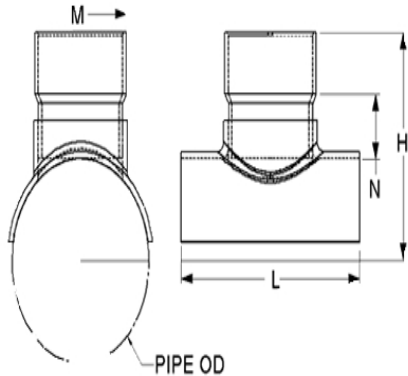

N = 2-5/16

H = 14-1/16

L = 9

M = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

