

Part No: 3965-813

Fabricated DWV

Glue-on Saddles

Desc: 20X3 PVC STUB SADDLE SOC SCH80 N.P.R.

MSRP: 308.36

Part Code: 400

Weight(lbs): 7.765

Weight(kg): 3.522

Weight(gm): 3522


Size: 20 X 3

Color: GRAY

Material: PVC

Schedule SCH 80 DWV Stub Saddle

Connection Socket

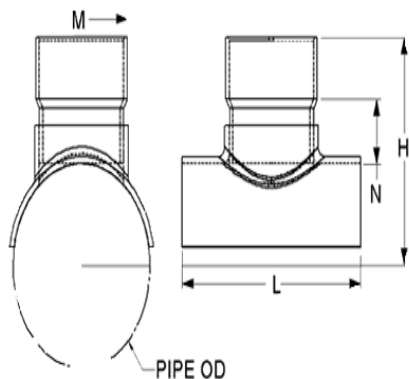

H = 15-1/8

L = 11-1/2

M = 4-1/8

N = 2-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

