

Part No: 3975-080

Fabricated DWV

Wyes

Desc: 8 PVC WYE SOC SCH80 N.P.R.

MSRP: 559.59

Part Code: 400

Weight(lbs): 28.528

Weight(kg): 12.94

Weight(gm): 12940

Size: 8


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Wye

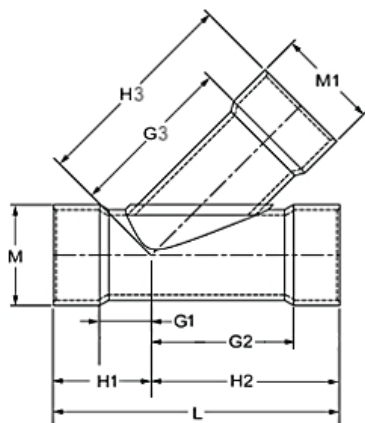

G1 = 5-1/16

G2 = 13-11/16

G3 = 15-7/8

H1 = 9-5/16

H2 = 17-15/16

H3 = 20-1/8

L = 27-1/4

M = 9- 5/8

M1 = 9-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

