

Part No: 3975-120

Fabricated DWV

Wyes

Desc: 12 PVC WYE SOC SCH80 N.P.R.

MSRP: 1511.13

Part Code: 400

Weight(lbs): 83.004

Weight(kg): 37.65

Weight(gm): 37650

Size: 12


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Wye

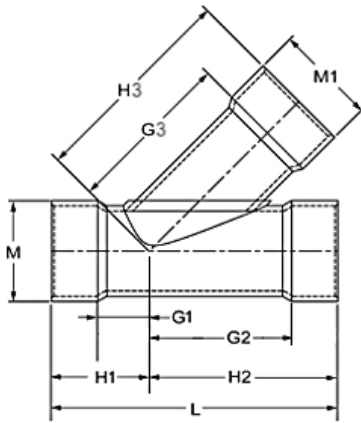

G1 = 7-1/8

G2 = 19-7/8

G3 = 21-13/16

H1 = 13-3/8

H2 = 26-1/8

H3 = 28-1/16

L = 39-1/2

M = 14- 1/8

M1 = 14-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

