

Part No: 3975-160C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 16 CPVC WYE SOC SCH80 N.P.R.

MSRP: 18656.7

Part Code: 099

Weight(lbs): 184.218

Weight(kg): 83.56

Weight(gm): 83560


Size: 16

Color: GRAY

Material: CPVC

Type Standard

Connection Socket x Socket x Socket

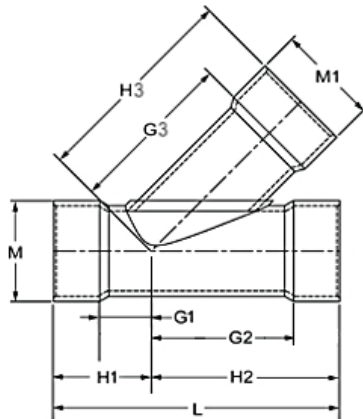

H1 = 18-1/8

H2 = 34-1/8

H3 = 34-1/8

L = 52-1/4

M = 17-11/16

M1 = 17-11/16

G1 = 10-1/8

G2 = 26-1/8

G3 = 26-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

