

Part No: 3975-623C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 10X3 CPVC RED WYE SOC SCH80 N.P.R.

MSRP: 1211.63

Part Code: 099

Weight(lbs): 33.466

Weight(kg): 15.18

Weight(gm): 15180


Size: 10 X 3

Color: GRAY

Material: CPVC

Type Reducing

Connection Socket x Socket x Socket

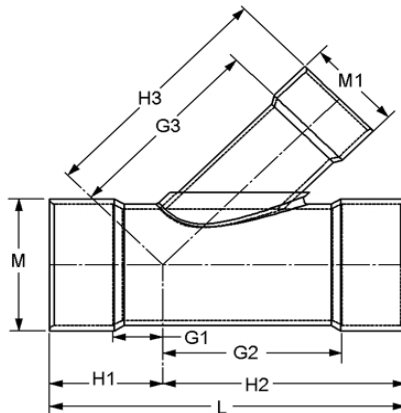

G1 = 3/4

G2 = 11-1/2

G3 = 13

H3 = 15-1/4

L = 22-3/4

M = 11-15/16

M1 = 4-1/8

H1 = 6

H2 = 16-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

