

Part No: 3975-663C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 12X3 CPVC RED WYE SOC SCH80 N.P.R.

MSRP: 1675.62

Part Code: 099

Weight(lbs): 44.624

Weight(kg): 20.241

Weight(gm): 20241


Size: 12 X 3

Color: GRAY

Material: CPVC

Type Reducing

Connection Socket x Socket x Socket

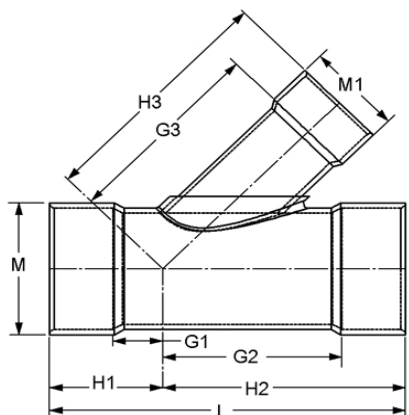

G1 = 1/8

G2 = 4-1/8

G3 = 14-5/16

H3 = 16-9/16

L = 25-1/2

M = 14-1/8

M1 = 4-1/8

H1 = 6-3/8

H2 = 19-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

