

Part No: 3975-670C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 12X10 CPVC RD WYE SOC SCH80 N.P.R.

MSRP: 2753.48

Part Code: 099

Weight(lbs): 80.319

Weight(kg): 36.432

Weight(gm): 36432


Size: 12 X 10

Color: GRAY

Material: CPVC

Type Reducing

Connection Socket x Socket x Socket

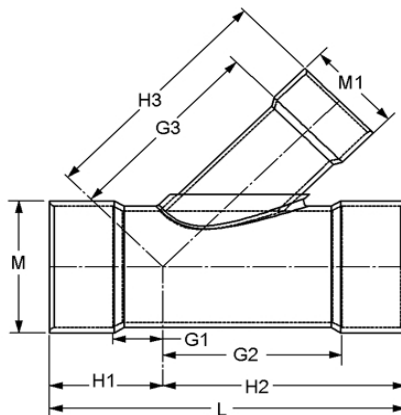

G1 = 5-3/4

G2 = 18-1/2

G3 = 20-3/16

H3 = 25-7/16

L = 36-3/4

M = 14-1/8

M1 = 11-15/16

H1 = 12

H2 = 24-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

