

Part No: 3975-694

Fabricated DWV

Wyes

Desc: 14X4 PVC RD WYE SOC SCH80 N.P.R.

MSRP: 1587.73

Part Code: 400

Weight(lbs): 55.116

Weight(kg): 25

Weight(gm): 25000

Size: 14 X 4


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

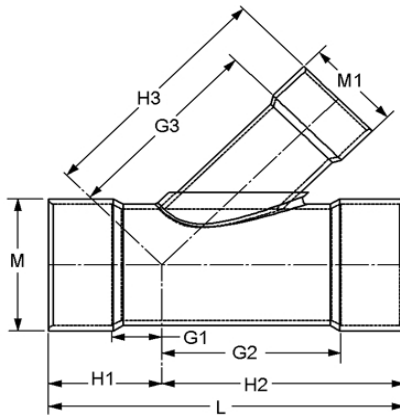

M1 = 5-3/16

H1 = 8-1/4

H2 = 22-1/4

G1 = 1-1/4

G2 = 15-1/4

G3 = 15-5/16

H3 = 17-9/16

L = 30-1/2

M = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

