

Part No: 3975-696

Fabricated DWV

Wyes

Desc: 14X6 PVC RD WYE SOC SCH80 N.P.R.

MSRP: 1739.03

Part Code: 400

Weight(lbs): 63.112

Weight(kg): 28.627

Weight(gm): 28627

Size: 14 X 6


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

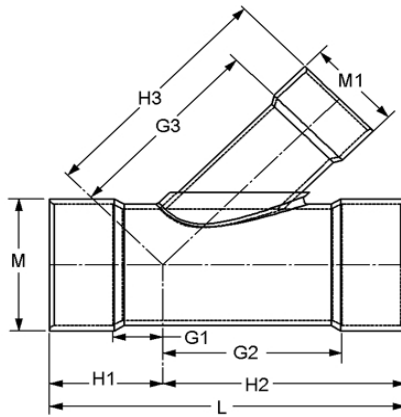

G1 = 2

G2 = 16

H2 = 23

G3 = 17-3/8

H3 = 20-5/8

L = 32

M = 15-1/2

M1 = 7-1/2

H1 = 9

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

