

Part No: 3975-702

Fabricated DWV

Wyes

Desc: 14X12 PVC RD WYE SOC SCH80 N.P.R.

MSRP: 2132.19

Part Code: 400

Weight(lbs): 100.081

Weight(kg): 45.396

Weight(gm): 45396

Size: 14 X 12


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

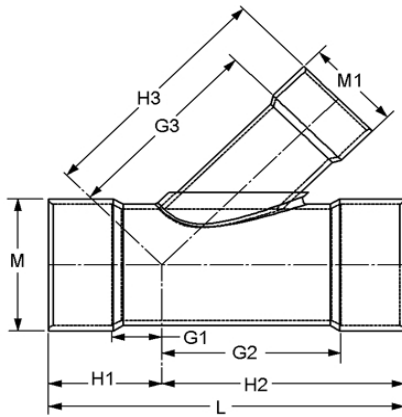

M = 15-1/2

M1 = 14-1/8

H1 = 14-1/4

H2 = 28-1/4

G1 = 7-1/4

G2 = 21-1/4

G3 = 22-9/16

H3 = 28-13/16

L = 42-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

