

Part No: 3975-754

Fabricated DWV

Wyes

Desc: 16X4 PVC RED WYE SOC SCH80 N.P.R.

MSRP: 1898.66

Part Code: 400

Weight(lbs): 78.903

Weight(kg): 35.79

Weight(gm): 35790

Size: 16 X 4


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

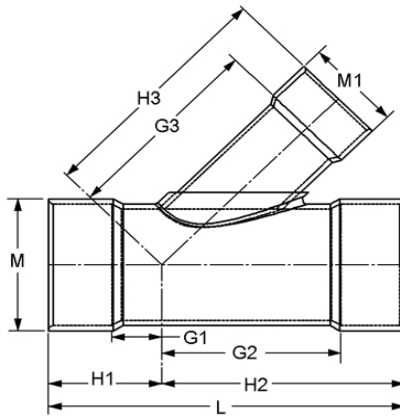

G1 = 1-1/8

G2 = 17-1/8

G3 = 16-5/8

H3 = 18-7/8

L = 34-1/4

M = 17-11/16

M1 = 5-3/16

H1 = 9-1/8

H2 = 25-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

