

Part No: 3975-760

Fabricated DWV

Wyes

Desc: 16X10 PVC RED WYE SOC SCH80 N.P.R.

MSRP: 2357.33

Part Code: 400

Weight(lbs): 116.345

Weight(kg): 52.773

Weight(gm): 52773

Size: 16 X 10


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

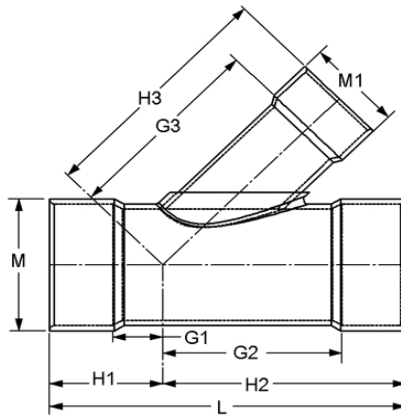

G1 = 5-1/8

G2 = 21-1/8

G3 = 22-1/4

H3 = 27-1/2

L = 42-1/4

M = 17-11/16

M1 = 11-15/16

H1 = 13-1/8

H2 = 29-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

