

Part No: 3975-764

Fabricated DWV

Wyes

Desc: 16X14 PVC RED WYE SOC SCH80 N.P.R.

MSRP: 3362.89

Part Code: 400

Weight(lbs): 144.079

Weight(kg): 65.353

Weight(gm): 65353

Size: 16 X 14


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

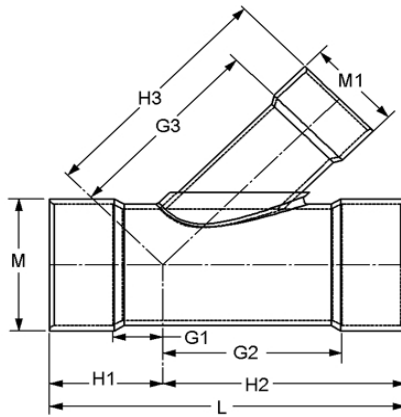

G1 = 7-7/8

G2 = 23-7/8

H2 = 13-7/8

G3 = 25-1/8

H3 = 32-1/8

L = 47-3/4

M = 17-11/16

M1 = 15-1/2

H1 = 15-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

