

Part No: 3975-786

Fabricated DWV

Wyes

Desc: 18X6 PVC RED WYE SOC N.P.R. SCH80

MSRP: 2495.11

Part Code: 400

Weight(lbs): 121.071

Weight(kg): 54.917

Weight(gm): 54917

Size: 18 X 6


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

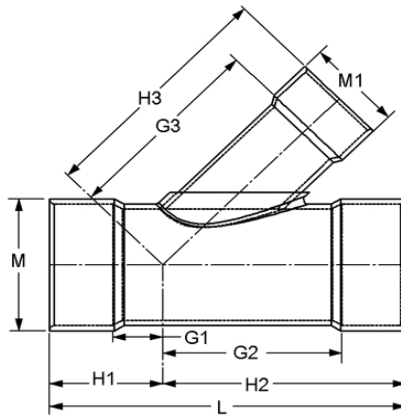

H2 = 27-9/16

G3 = 20-1/8

H3 = 23-3/8

L = 36-15/16

M = 19-7/8

M1 = 7-1/2

H1 = 9-3/8

G1 = 3/8

G2 = 18-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

