

Part No: 3975-914C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 24X14 CPVC RED WYE SOC SCH80 N.P.R.

MSRP: 28949.41

Part Code: 099

Weight(lbs): 398.733

Weight(kg): 180.862

Weight(gm): 180862


Size: 24 X 14

Color: GRAY

Material: CPVC

Type Reducing

Connection Socket x Socket x Socket

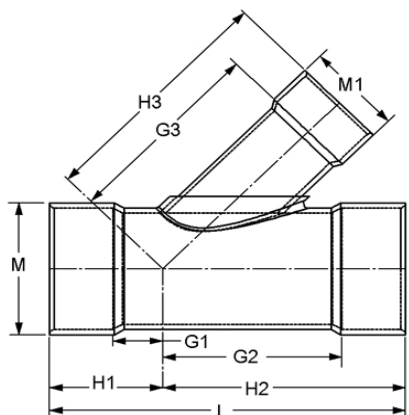

G1 = 6-1/4

G2 = 30-1/4

G3 = 30-1/4

H3 = 37-1/4

L = 60-1/2

M = 26-7/16

M1 = 15-1/2

H1 = 18-1/4

H2 = 42-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

