

Part No: 3975-920

Fabricated DWV

Wyes

Desc: 24X20 PVC RED WYE SOC SCH80 N.P.R.

MSRP: 8451.6

Part Code: 400

Weight(lbs): 381.554

Weight(kg): 173.07

Weight(gm): 173070

Size: 24 X 20


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket X Socket X Socket

Type Reducing Wye

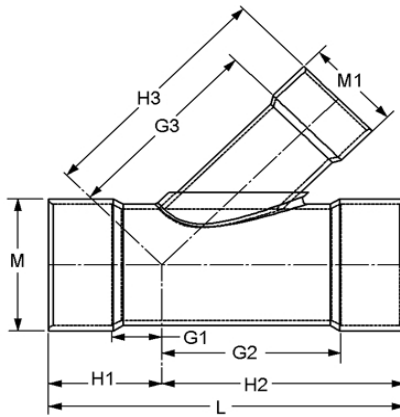

H3 = 44-3/16

L = 67-1/4

M = 26-7/16

M1 = 22-1/16

H1 = 21-5/8

H2 = 45-5/8

G1 = 9-5/8

G2 = 33-5/8

G3 = 34-3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

