

Part No: 3975-920C

**Fabricated CPVC Schedule 80 Wyes
DWV**

Desc: 24X20 CPVC RED WYE SOC SCH80 N.P.R.

MSRP: 37690.41

Part Code: 099

Weight(lbs): 372.894

Weight(kg): 169.142

Weight(gm): 169142


Size: 24 X 20

Color: GRAY

Material: CPVC

Type Reducing

Connection Socket x Socket x Socket

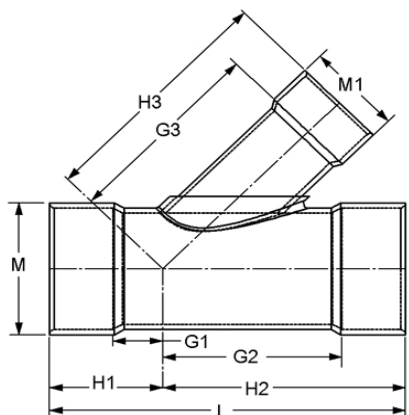

G1 = 9-5/8

G2 = 33-5/8

G3 = 34-3/16

H3 = 44-3/16

L = 67-1/4

M = 26-7/16

M1 = 22-1/16

H1 = 21-5/8

H2 = 45-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

