

Part No: 3976-040C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 4 CPVC DBL WYE SOC SCH80 N.P.R.

MSRP: 913.62

Part Code: 099

Weight(lbs): 9.259

Weight(kg): 4.2

Weight(gm): 4200


Size: 4

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket

Type Standard

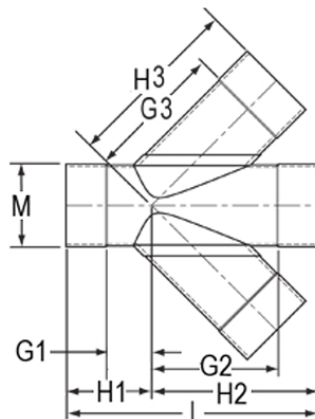

L = 18-3/8

M = 5-3/16

G1 = 4-11/16

G3 = 9-3/16

G2 = 9-3/16

H1 = 6-15/16

H3 = 11-7/16

H2 = 11-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

