

Part No: 3976-060

Fabricated DWV

Double Wye

Desc: 6 PVC DBL WYE SOC SCH80 N.P.R.

MSRP: 317.32

Part Code: 400

Weight(lbs): 20.384

Weight(kg): 9.246

Weight(gm): 9246

Size: 6


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Standard

Connection Socket x Socket x Socket x Socket

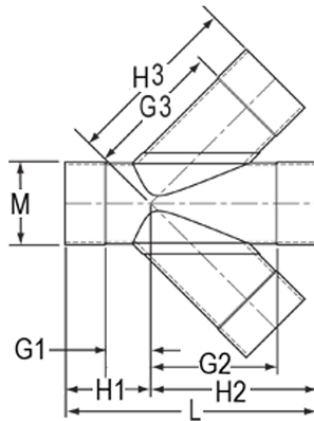

H2 = 14-13/16

L = 23

M = 7-1/2

G1 = 4-15/16

G3 = 12-5/8

G2 = 11-9/16

H1 = 8-3/16

H3 = 15-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

