

Part No: 3976-120C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 12 CPVC DBL-Y WYE SOC SCH80 N.P.R.

MSRP: 5537.27

Part Code: 099

Weight(lbs): 149.319

Weight(kg): 67.73

Weight(gm): 67730


Size: 12

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket

Type Standard

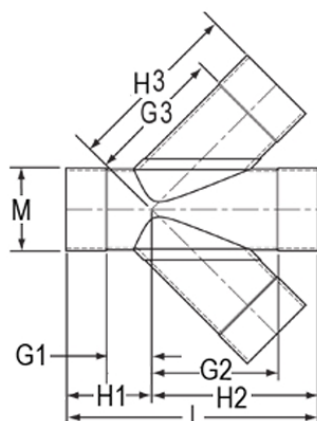

G1 = 7-1/8

G3 = 21-13/16

G2 = 19-7/8

H1 = 13-3/8

H3 = 28-1/16

H2 = 26-1/8

L = 39-1/2

M = 14-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

