

Part No: 3976-530C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 6X3 CPVC RED DBL-WYE SOC SCH80 N.P.R.

MSRP: 961.18

Part Code: 099

Weight(lbs): 12.566

Weight(kg): 5.7

Weight(gm): 5700


Size: 6 X 3

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket

Type Reducing

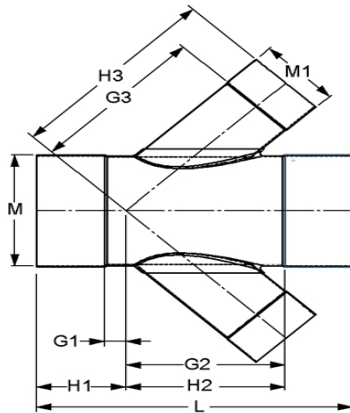

G1 = 2-15/16

G2 = 9-9/16

G3 = 10-5/16

H1 = 6-3/16

H2 = 12-13/16

H3 = 12-9/16

L = 19

M = 7-1/2

M1 = 4-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

