

Part No: 3976-621

Fabricated DWV

Double Wye

Desc: 10X2 PVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 621.48

Part Code: 400

Weight(lbs): 23.966

Weight(kg): 10.871

Weight(gm): 10871

Size: 10 X 2


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

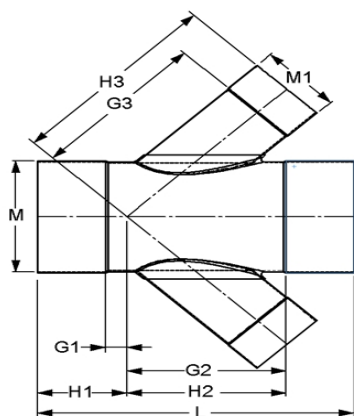

G1 = 1/4

G2 = 10-1/2

G3 = 11-7/8

H1 = 5

H2 = 15-3/4

H3 = 13-5/8

L = 20-3/4

M = 11-15/16

M1 = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

