

Part No: 3976-663

Fabricated DWV

Double Wye

Desc: 12X3 PVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 1033.89

Part Code: 400

Weight(lbs): 42.247

Weight(kg): 19.163

Weight(gm): 19163

Size: 12 X 3


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

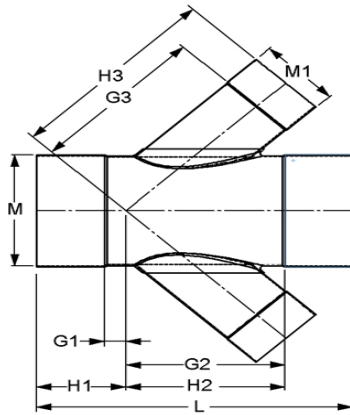

G1 = 1/8

G2 = 12-7/8

G3 = 14-5/16

H1 = 6-3/8

H2 = 19-1/8

H3 = 16-9/16

L = 25-1/2

M = 14-1/8

M1 = 4-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

