

Part No: 3976-670

Fabricated DWV

Double Wye

Desc: 12X10 PVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 1683.04

Part Code: 400

Weight(lbs): 93.196

Weight(kg): 42.273

Weight(gm): 42273

Size: 12 X 10


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

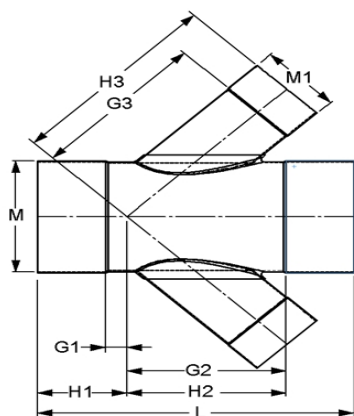

G1 = 5-3/4

G2 = 18-1/2

G3 = 20-3/16

H1 = 12

H2 = 24-3/4

H3 = 25-7/16

L = 36-3/4

M = 14-1/8

M1 = 11-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

