

Part No: 3976-691C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 14X2 CPVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 3456.49

Part Code: 099

Weight(lbs): 49.205

Weight(kg): 22.319


Weight(gm): 22319

Size: 14 X 2

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket
Type Reducing

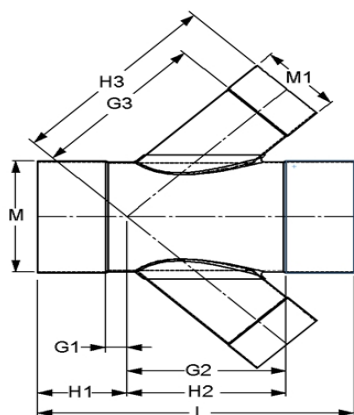

G1 = 1/4

G2 = 13-3/4

G3 = 13-15/16

H1 = 6-3/4

H2 = 20-3/4

H3 = 15-11/16

L = 27-1/2

M = 15-1/2

M1 = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

