

Part No: 3976-753C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 16X3 CPVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 5595.74

Part Code: 099

Weight(lbs): 79.049

Weight(kg): 35.856


Weight(gm): 35856

Size: 16 X 3

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket
Type Reducing

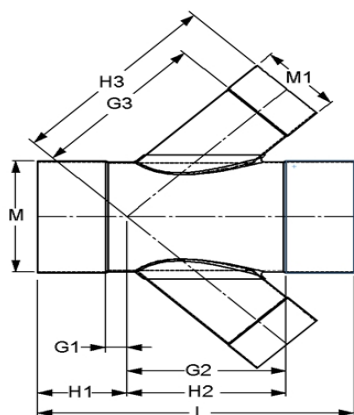

G1 = 1/8

G2 = 15-7/8

G3 = 16-3/8

H1 = 7-7/8

H2 = 23-7/8

H3 = 18-5/8

L = 31-3/4

M = 17-11/16

M1 = 4-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

