

Part No: 3976-784

Fabricated DWV

Double Wye

Desc: 18X4 PVC RED DBL WYE SOC N.P.R. SCH80

MSRP: 2756.59

Part Code: 400

Weight(lbs): 126.898

Weight(kg): 57.56

Weight(gm): 57560

Size: 18 X 4


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

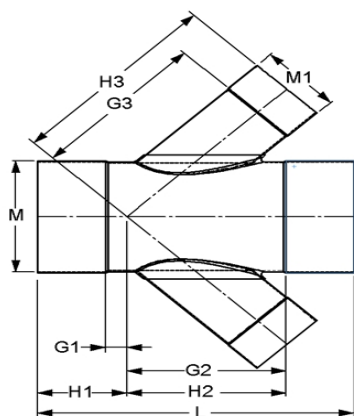

H3 = 20-1/8

L = 36

M = 19-7/8

M1 = 5-3/16

G1 = 0

G2 = 18

G3 = 17-7/8

H1 = 9

H2 = 27

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

