

Part No: 3976-818

Fabricated DWV

Double Wye

Desc: 20X8 PVC RED DBL WYE SOC N.P.R.SCH80

MSRP: 3902.49

Part Code: 400

Weight(lbs): 186.366

Weight(kg): 84.534

Weight(gm): 84534

Size: 20 X 8


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

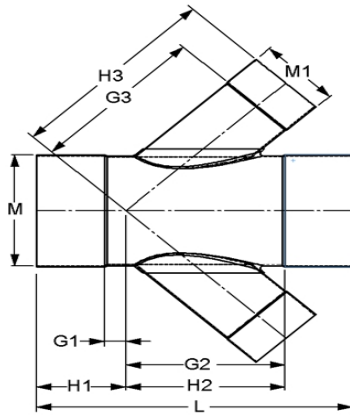

G1 = 2-5/8

G2 = 22-5/8

M1 = 9-5/8

G3 = 23-3/16

H1 = 12-5/8

H2 = 32-5/8

H3 = 27-7/16

L = 45-1/4

M = 22-1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

