

Part No: 3976-822

Fabricated DWV

Double Wye

Desc: 20X12 PVC RED DBL WYE SOC N.P.R. SCH80

MSRP: 4967.63

Part Code: 400

Weight(lbs): 245.769

Weight(kg): 111.479

Weight(gm): 111479

Size: 20 X 12


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

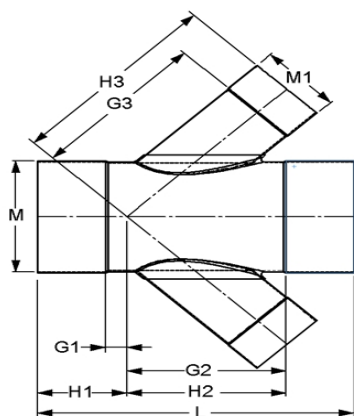

H3 = 32-11/16

L = 51-1/4

M = 22-1/16

M1 = 14-1/8

G1 = 5-5/8

G2 = 25-5/8

G3 = 26-7/16

H1 = 15-5/8

H2 = 35-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.





L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

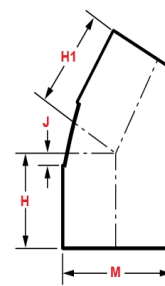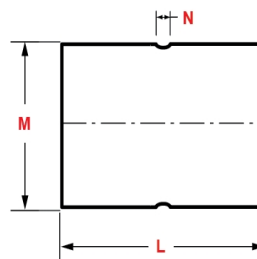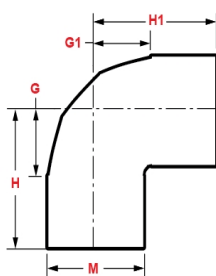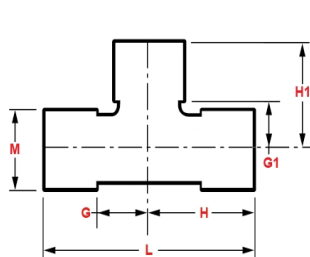

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006